



Confidence at Every Step


Beverage Quality Testing Solutions
to Satisfy Evolving Tastes

A Recipe for Success

Feel confident at every step of your beverage testing. Find the right products to help you perform quality control on water, milk, beer, wine, spirits, juices, sodas, sports drinks, coffee, tea, plant-based milk alternatives, and other alcoholic and non-alcoholic beverages.

Your One-Stop Shop

Access over **1.7 million** food and beverage testing products in North America from close to **6,500 suppliers**.

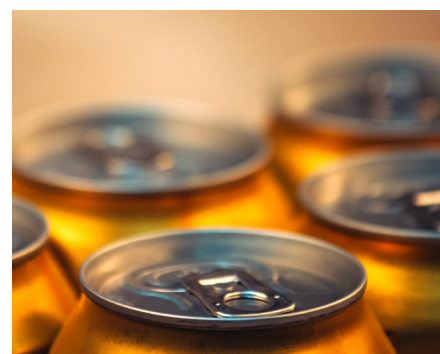

Beverage Microbiology

- Autoclaves
- Filtration systems and manifolds
- Incubation
- Media
- Petri dishes
- Serological pipettes

Beverage Chemistry

- Chromatography equipment and consumables
- Glassware
- pH meters, electrodes, and buffers
- Titration systems

Beverage Quality Control (QA/QC)

- Ion, pH, DO, and BOD benchtop and portable meters
- Moisture analyzers
- Pesticide kits
- Refractometers
- Spectrophotometers
- Standards and buffers
- Thermometers

Essentials for Beverage Analysis

Visit fishersci.com or fishersci.ca, or click the links below to browse the following product categories.

Microbiology – [U.S.](#) | [CA](#)

From sample collection and microbial identification to colony counting and sample storage, find microbiology testing products from brands you trust for every step of your workflow.



Filters and Filtration – [U.S.](#) | [CA](#)

Browse devices and hardware for the filtration, analysis, and purification of samples, including complete kits, bottle-top filters, plates, storage bottles, stirred cells, membranes, and more.



Refractometers – [U.S.](#) | [CA](#)

Shop instruments designed to measure a sample's refractive index or polarization of light, available in benchtop or portable sizes and with accessories and replacement parts.



Electrochemistry – [U.S.](#) | [CA](#)

Assess acidity and alkalinity, conductivity, specific ion concentrations, and dissolved oxygen in water, wastewater, and other solutions with meters, probes, electrodes, and more.



Turbidity – [U.S.](#) | [CA](#)

Measure and compare a sample's turbidity, also known as cloudiness, with the right equipment, accessories, replacement parts, standards, and products for calibration.



Hydrometers – [U.S.](#) | [CA](#)

Explore instruments used to measure the specific gravity, relative density, and/or percent alcohol content of liquid samples, available in various calibrations.



Cold Storage – [U.S.](#) | [CA](#)

Choose upright, undercounter, or benchtop laboratory refrigerator units with solid or glass doors for your reagents, media, proteins, and other samples and solutions.



Chromatography – [U.S.](#) | [CA](#)

Find products for liquid, gas, and life sciences chromatography, including solvents and standards, columns and cartridges, and more.



Chemicals – [U.S.](#) | [CA](#)

Let our team of specialists help you find the right research chemicals, production chemicals, bulk and custom chemicals, and more for your exact needs and budget.



Liquid Samplers – [U.S.](#) | [CA](#)

Collect liquid samples from larger reservoirs using scoops, dippers, drum samplers, and more available in chemical-resistant varieties for use with caustic materials.



Visit fishersci.com or fishersci.ca to shop the following products.

Beverage Testing Supplies

Visit fishersci.com or fishersci.ca to shop the following products.

Microbiology

Description	Quantity	Cat. No.
MilliporeSigma™ EZ-Fit™ Filtration Units, 0.45 µm Pore Size		
100 mL, Black Membrane, Bulk Packaging	48/Pack	EFHAB100B U.S. CA
100 mL, Black Membrane, Individual Packaging	48/Pack	EFHAB100I U.S. CA
250 mL, Black Membrane, Bulk Packaging	48/Pack	EFHAB250B U.S. CA
250 mL, Black Membrane, Individual Packaging	48/Pack	EFHAB250I U.S. CA
100 mL, White Membrane, Bulk Packaging	48/Pack	EFHAW100B U.S. CA
100 mL, White Membrane, Individual Packaging	48/Pack	EFHAW100I U.S. CA
250 mL, White Membrane, Bulk Packaging	48/Pack	EFHAW250B U.S. CA
250 mL, White Membrane, Individual Packaging	48/Pack	EFHAW250I U.S. CA
MilliporeSigma EZ-Fit Filtration Units, 0.85 µm Pore Size		
100 mL, Black Membrane, Bulk Packaging	48/Pack	EFAAB10BS U.S. CA
250 mL, Black Membrane, Bulk Packaging	48/Pack	EFAAB25BS U.S. CA
100 mL, White Membrane, Bulk Packaging	48/Pack	EFAAW10BS U.S. CA
250 mL, White Membrane, Bulk Packaging	48/Pack	EFAAW25BS U.S. CA
MilliporeSigma EZ-Fit Filtration Units, 0.22 µm Pore Size		
100 mL, White Membrane, Individual Packaging	48/Pack	EFGSW10IS U.S. CA
100 mL, White Membrane, Bulk Packaging	48/Pack	EFGSW10MS U.S. CA
MilliporeSigma EZ-Fit Filtration Units, 0.45 µm Pore Size		
100 mL, Black Membrane, Bulk Packaging	48/Pack	EFHAB10MS U.S. CA
250 mL, Black Membrane, Bulk Packaging	48/Pack	EFHAB25BS U.S. CA
100 mL, White Membrane, Bulk Packaging	48/Pack	EFHAW10MS U.S. CA
250 mL, White Membrane, Bulk Packaging	48/Pack	EFHAW25BS U.S. CA
100 mL, White Membrane, Individual Packaging	48/Pack	EFHVW10IS U.S. CA
MilliporeSigma EZ-Fit Manifolds		
Rubber Stopper Tulip, 3 Places	Each	EZFITH0LD3 U.S. CA
Rubber Stopper Tulip, 1 Place	Each	EZFITH0LD1 U.S. CA
Rubber Stopper Tulip, 6 Places	Each	EZFITH0LD6 U.S. CA
Microfil Funnels and Membranes, 3 Places	Each	EZFITMIC03 U.S. CA
Microfil Funnels and Membranes, 1 Place	Each	EZFITMIC01 U.S. CA
Microfil Funnels and Membranes, 6 Places	Each	EZFITMIC06 U.S. CA
Microfil V or Microfil S Filtration Units, 3 Places	Each	EZFITL0W03 U.S. CA
Microfil V or Microfil S Filtration Units, 1 Place	Each	EZFITL0W01 U.S. CA
Microfil V or Microfil S Filtration Units, 6 Places	Each	EZFITL0W06 U.S. CA
MilliporeSigma EZ-Fit Manifolds for EZ-Fit Filtration Units		
Stainless Steel, 1 Place	Each	EZFREAG57MI U.S. CA
Stainless Steel, 6 Places	Each	EZFITEFUN6 U.S. CA
MilliporeSigma™ EZ-Fluo™ Products		
Reagent Kits	Each	EFAAB10BS U.S. CA
MilliporeSigma™ EZ-Stream™ Products		
Vacuum Pumps	Each	EZSTREAM1 U.S. CA

Filters and Filtration

Description	Quantity	Cat. No.	
Cytiva's Whatman™ Grade 934-AH RTU Glass Microfiber Filters	100/Pack	14-380-935	U.S. CA
Cytiva's Whatman Grade 934-AH Binder-Free Glass Microfiber Filters	100/Pack	09-873DD	U.S. CA
Cytiva's Whatman GD/X Nylon Syringe Filters	150/Pack	09-927-26D	U.S. CA
Cytiva's Whatman GD/X Regenerated Cellulose Syringe Filters	150/Pack	05-713-929	U.S. CA
Cytiva's Whatman Grade 2V Folded Qualitative Filter Papers, 150 mm	100/Pack	09-832B	U.S. CA
Cytiva's Whatman Grade 2V Folded Qualitative Filter Papers, 320 mm	100/Pack	09-832E	U.S. CA
Cytiva's Whatman Grade 2V Folded Qualitative Filter Papers, 500 mm	100/Pack	09-832G	U.S. CA
Cytiva's Whatman Mixed Cellulose Ester Membrane Filters	100/Pack	09-806-216	U.S. CA
Cytiva's Whatman Sterile Mixed Cellulose Ester Membranes, ME 25	100/Pack	09-927-255	U.S. CA
Cytiva's Whatman Sterile Mixed Cellulose Ester Gridded Membranes	100/Pack	09-940-042	U.S. CA

Electrochemistry

Description	Quantity	Cat. No.	
Thermo Scientific™ Orion Star™ A214 pH/ISE Benchtop Meters			
Includes Stand	Each	13-645-539	U.S. CA
Includes Thermo Scientific™ Orion™ ROSS Ultra™ Glass-Body pH Electrode, ATC Probe, Stirrer Probe, Solutions, and Stand	Each	13-645-541	U.S. CA
Includes Ammonia Electrode and Solutions, ROSS Ultra Glass-Body pH Electrode, ATC Probe, Stirrer Probe, and Stand	Each	13-645-542	U.S. CA
Includes Fluoride Electrode and Solutions, ROSS Ultra Glass-Body pH Electrode, ATC Probe, Stirrer Probe, and Stand	Each	13-645-543	U.S. CA
Includes ROSS Sodium Electrode and Solutions, ROSS Ultra Glass-Body pH Electrode, ATC Probe, Stirrer Probe, and Stand	Each	13-645-544	U.S. CA
Thermo Scientific Orion Star T940 All-in-One Titrator and Kits			
Electrode Only	Each	13-642-967	U.S. CA
Standard ROSS Kit	Each	13-642-968	U.S. CA
ROSS Sure-Flow Kit	Each	13-642-969	U.S. CA

Standards

Description	Quantity	Cat. No.	
Ricca Chemical™ Ethyl Alcohol Standard, 10% (v/v)	500 mL	R2919100500	U.S. CA
MilliporeSigma™ Supelco™ TraceCERT™ Ethanol Solution, 2,000 µg/mL in Methanol	1 mL	11-102-0270	U.S. CA
MilliporeSigma Supelco TraceCERT Cannabis Terpene Mix A, 2,000 µg/mL	1 mL	11-101-7136	U.S. CA
MilliporeSigma Supelco TraceCERT Cannabis Terpene Mix B, 2,000 µg/mL	1 mL	11-101-7137	U.S. CA
MilliporeSigma Supelco Glycitein, ≥98.0% (HPLC)	10 mg	11-101-4157	U.S. CA

Turbidity

Description	Quantity	Cat. No.	
Thermo Scientific™ Orion™ AQUAfast™ AQ3010 Turbidity Meters	Each	13-644-504	U.S. CA
Thermo Scientific Accessories for Orion AQUAfast AQ3010 Turbidity Meters	Each	13-644-503	U.S. CA
Thermo Scientific™ Orion™ AQ4500 Turbidimeters	Each	13-650-100	U.S. CA
Labconco™ WaterPro™ Filters	Each	16-307-17	U.S. CA
Lovibond™ Infrared Lab Turbidimeters	Each	09-053-500	U.S. CA
Cole Parmer™ Oakton™ Portable Turbidity Meter Kits, White Light	Each	13-000-101	U.S. CA
Cole Parmer Oakton Portable Turbidity Meter Kits, Infrared	Each	13-000-102	U.S. CA

Hydrometers

Description	Quantity	Cat. No.	
Fisherbrand™ Precision Specific Gravity Hydrometer Sets	Each	11-583D	U.S. CA
Fisherbrand Specific Gravity Hydrometers	Each	11-520A	U.S. CA
Fisherbrand Baume Hydrometers	Each	11-571A	U.S. CA
DWK Life Sciences™ Kimble™ Chase™ Tall-Form High Precision Specific Gravity Hydrometers	Each	13-757-045	U.S. CA
DWK Life Sciences Kimble Chase Plain Form API ASTM Hydrometers	Each	10-310-338	U.S. CA

Portable Refractometers

Description	Quantity	Cat. No.	
Fisherbrand Handheld Digital Wine Refractometers	Each	12-561-353	U.S. CA
Fisherbrand Handheld Analog Brix/Sucrose Refractometers	Each	12-561-337	U.S. CA
Reichert™ Handheld Digital Brix Refractometers	Each	13-975-411	U.S. CA
Fisherbrand Handheld Digital Brix/RI Refractometers	Each	12-561-345	U.S. CA
METTLER TOLEDO™ Refracto™ 30GS Portable Refractometers	Each	01-916-222	U.S. CA
METTLER TOLEDO Refracto 30PX Portable Refractometers	Each	01-916-221	U.S. CA
Laxco™ Handheld Analog Brix/Sucrose Refractometers	Each	IRB32ATC	U.S. CA

Benchtop Refractometers

Description	Quantity	Cat. No.	
METTLER TOLEDO™ Easy Bev Refractometers	Each	13-940-097	U.S. CA
METTLER TOLEDO Easy R40 Refractometers	Each	13-940-095	U.S. CA
METTLER TOLEDO Easy Brix Refractometers	Each	13-940-096	U.S. CA

Chromatography

Description	Quantity	Cat. No.	
Thermo Scientific™ Accucore™ aQ C18 Polar Endcapped HPLC Columns	Each	17-326-102130	U.S. CA
Thermo Scientific Accucore RP-MS HPLC Columns	Each	17-626-102130	U.S. CA
Thermo Scientific Accucore C30 HPLC Columns	Each	03-452-136	U.S. CA
Thermo Scientific Accucore 150 Amide HILIC HPLC Columns	Each	03-452-147	U.S. CA
Thermo Scientific Accucore RP-MS HPLC Columns	Each	17-626-102130	U.S. CA
Thermo Scientific Non-Assembled Clear Screw Thread Wide Opening Autosampler Vial Kits, 9 mm	Each	3376605	U.S. CA
Thermo Scientific Glass Snap Top Vials, Routine Range, 11 mm	100/Pack	3251847	U.S. CA
Thermo Scientific Autosampler Snap-It Caps, 11 mm	100/Pack	03-246-316	U.S. CA

Solvents


Description	Quantity	Cat. No.	
Fisher Chemical™ IPA (Isopropyl Alcohol), 70% v/v	4 L	A459-4	U.S. CA
Fisher Chemical 2-Propanol (Certified ACS)	4 L	A416P-4	U.S. CA
Fisher Chemical Methanol (HPLC)	4 L	A452-4	U.S. CA
Fisher Chemical Methanol (Certified ACS)	4 L	A412-4	U.S. CA
Fisher Chemical Acetonitrile (HPLC)	4 L	A998-4	U.S. CA
Fisher Chemical™ Optima™ Acetonitrile, LC/MS Grade	4 L	A955-4	U.S. CA
Fisher Chemical Optima Acetonitrile for HPLC and GC	4 L	A996-4	U.S. CA

Testing and Certified Reference Standards

Description	Quantity	Cat. No.	
MilliporeSigma™ Supelco™ (+)-Catechin, ≥99.0% (HPLC)	10 mg	11-101-3231	U.S. CA
MilliporeSigma Supelco trans-p-Coumaric Acid, ≥98.0% (HPLC)	50 mg	11-101-4350	U.S. CA
MilliporeSigma Supelco Ochratoxin A from Aspergillus Ochraceus	5 mg	11-101-8035	U.S. CA
TCI America™ Atrazine, 97.0+%	5 g	A16505G	U.S. CA
SPEX CertiPrep™ Caffeine	1 mL	S705	U.S. CA
TCI America Caffeine, 98.0+%	500 g	C2042500G	U.S. CA
MilliporeSigma Supelco TraceCERT Cannabis Terpene Mix A, 2,000 µg/mL	1 mL	11-101-7136	U.S. CA
Restek™ Cannabidiol (CBD) Standard in P&T Methanol Solvent, 1,000 µg/mL	1 mL	06-722-452	U.S. CA
MilliporeSigma Supelco TraceCERT Heavy Metal Mix VII for Cannabis Testing, Certified Reference Material	100 mL	11-102-2380	U.S. CA
MilliporeSigma™ Supelco™ phyproof™ Lavandulyl Acetate, ≥90% (GC)	100 mg	11-100-2213	U.S. CA
Thermo Scientific™ (±)-Camphor, 96%	100 g	AAA1093622	U.S. CA
Thermo Scientific Erythrosin B, Pure, Certified	25 g	AC409450250	U.S. CA
Thermo Scientific α-D-Lactose Monohydrate, ACS	500 g	AA3621836	U.S. CA
MilliporeSigma Supelco Lactose Standard for IC, 1000 mg/L in H ₂ O	50 mL	11-100-4489	U.S. CA
SPEX CertiPrep Calcium Standard for ICP/MS	30 mL	CLCA22M	U.S. CA
SPEX CertiPrep Vitamin D3	1 mL	S3815	U.S. CA
TCI America Erythrosine B, 95.0+%	25 g	T055725G	U.S. CA
Thermo Scientific™ ImmunoCAP™ Seed, Legume, and Nut Allergens, Soybean Glycine Max	16/Pack	14-411-501P	U.S. CA
Thermo Scientific ImmunoCAP Seed, Legume, and Nut Allergens, Peanut Arachis Hypogaea	16/Pack	14-412-601P	U.S. CA
Thermo Scientific ImmunoCAP Seed, Legume, and Nut Allergens, Sesame Seed, Sesamum Indicum	16/Pack	14-417-501P	U.S. CA
MilliporeSigma™ Supelco™ PESTANAL™ Prochloraz	250 mg	11-102-0070	U.S. CA

Visit fishersci.com or fishersci.ca to shop the following products.

 Other Popular Items



Water
[U.S.](#) | [CA](#)



Incubators
[U.S.](#) | [CA](#)



**Microbiological Specimen
Transport and Collection Kits**
[U.S.](#) | [CA](#)




Microscopes
[U.S.](#) | [CA](#)



Petri Dishes
[U.S.](#) | [CA](#)



Microscope Slides
[U.S.](#) | [CA](#)

 

Inoculating Loops and Needles
[U.S.](#) | [CA](#)



Stains and Dyes
[U.S.](#) | [CA](#)



**Microbiological Media and
Media Additives**
[U.S.](#) | [CA](#)



Colony Counters
[U.S.](#) | [CA](#)



**Microplate Readers and
Accessories**
[U.S.](#) | [CA](#)

Suppliers



fisherbrand



METTLER TOLEDO

**MILLIPORE
SIGMA**

Nasco

thermo scientific

Visit fishersci.com or fishersci.ca to shop the following products.

Distributed by Fisher Scientific. Contact us today:

In the United States

Order online: fishersci.com

Call customer service: 1-800-766-7000

In Canada

Order online: fishersci.ca

Call customer service: 1-800-234-7437



© 2022 Thermo Fisher Scientific Inc. All rights reserved.

Trademarks used are owned as indicated at fishersci.com/trademarks.

22-702-1480 KP 07/22 BN4438884-NA