

# EXTRAORDINARY HAND PROTECTION

**Scion700™ Nitrile Exam Gloves with Low Dermatitis Potential** are created from the latest patented LOW DERMA™ technology accelerator-free nitrile\*, delivering improved stretch and chemical permeation resistance, excellent tactile sensitivity and softness, and reduced risk of glove-related allergic contact dermatitis.



## PRODUCT SPECIFICATIONS

**100% Nitrile | Accelerator-Free | Finger-Textured | Powder-Free**

ASTM D6319 & EN 455 Nitrile Exam Gloves for Medical Application  
 ASTM F1671 Viral Penetration Test  
 ASTM D6978 Chemotherapy Drugs and Fentanyl Citrate Tested  
 US FDA 21 CFR 177.2600 & EU 10/2011 (EN1186) for Food Handling  
 PPE 89/686/EEC, Cat III; PPE Regulation (EU) 2016/425  
 Meets ASTM D6978 and USP 800 PPE requirement for use of chemotherapy gloves when handling hazardous drugs.

<b>GLOVE THICKNESS</b> Typical Values (mm)	<b>GLOVE LENGTH</b> Typical Values (mm)
Cuff 0.05 - 0.06	245 - 250 (9")
Palm 0.06 - 0.07	
Fingertip 0.08 - 0.10	<b>AQL</b>

<b>PHYSICAL PROPERTIES</b> Typical Values	Watertight Test 1.5
Tensile Strength 30-34 MPa	<b>PACKAGING</b>
Elongation 540-560%	300 Gloves/Box
	10 Boxes/Case
	(XL 250 Gloves/Box)

**Free Samples:** [bit.ly/scion700](http://bit.ly/scion700)

\*Patent [www.lowderma.com/patents](http://www.lowderma.com/patents)

**For more information, please contact:**

## FEATURES & BENEFITS



Patented Technology\*




**NO** Thiurams, Carbamates or Mercaptobenzothiazoles (MBTs.)

**First FDA Cleared Fentanyl Permeation Labeling Claim - Protection You Can Trust**


>240 Minutes; 510(k) Granted by U.S. FDA

**300-Count Box** maximizes space, reduces waste and minimizes cost.

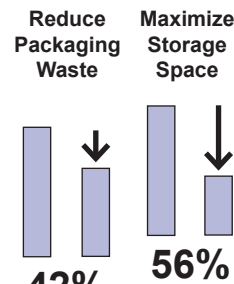

\*Compared to 100-ct boxed gloves, 40' container load.

**Excellent Chemical Resistance**  
(BS EN 16523-1:2015)

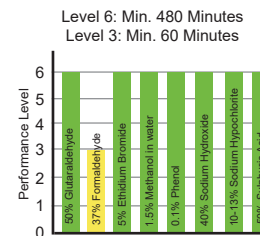

Fits standard size glove box holder.

**Chemotherapy Drug & Fentanyl Permeation Tested**

- No Breakthrough After 240 Min.
- Cisplatin
- Cyclophosphamide (Cytoxan)
- Cytarabine
- Dacarbazine
- Doxorubicin Hydrochloride
- Etoposide
- Fluorouracil
- Ifosfamide
- Methotrexate
- Mitomycin C
- Mitoxantrone
- Paclitaxel (Taxol)
- Vincristine Sulfate
- Thiotepa - 90 Minutes
- Carmustine - 10 Minutes
- Fentanyl Citrate >240 Minutes**

Size	Hourglass Item No.	Fisher Scientific Cat. No.	Price
XS	700	17-900-912	
S	701	17-900-913	
M	702	17-900-914	
L	703	17-900-915	
XL	704	17-900-916	

Distributed by Fisher Scientific. Contact us today:

**In the United States**  
 Order online: [fishersci.com](http://fishersci.com)  
 Call customer service: 1-800-766-7000

**In Canada**  
 Order online: [fishersci.ca](http://fishersci.ca)  
 Call customer service: 1-800-234-7437

